

Series 6700 booster

Parts list


File No: 6062.104

Date: FEBRUARY 20, 2014


Supersedes: NEW

Date: NEW

Series 6700 Booster

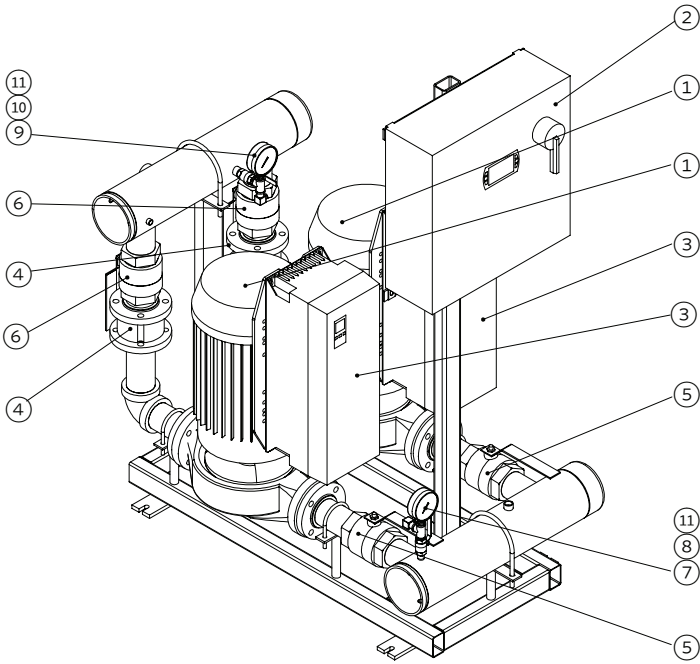

6722/3IVS

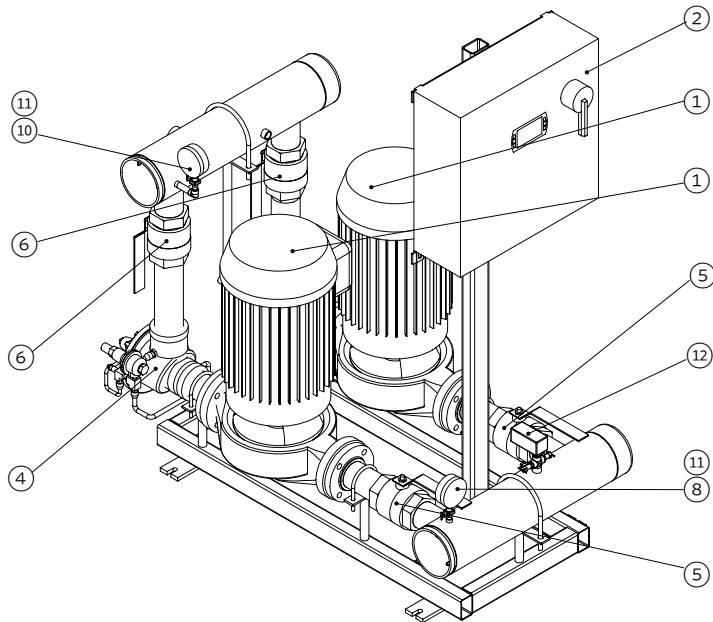

6722/3

ITEM 1: PUMP

See File no. 6043.129 for 4380 pump parts or See File no. 6043.132 for 4300 pump parts

6700 SERIES BOOSTER MODEL	PART NUMBER	QTY PER BOOSTER
6722	4300	2
6723	4380	2
6732	4300	3
6733	4380	3

ITEM 2: CONTROL PANEL

Please contact Armstrong service department with unit serial number for replacement control panel

ITEM 3: IVS DRIVE

See File no. 6094.100 for IVS drive parts

*IVS systems only.

ITEM 4: MAIN CHECK VALVE / MAIN PRV

VALVE SIZE	CHECK VALVE PART NUMBER*	PRV PART NUMBER†	QTY PER PUMP
1.5"	D975040-506	D975030-006	1
2"	D975040-507	D975030-007	1
2.5"	D975041-108	D975030-008	1
3"	D975041-109	D975030-009	1

* 1.5" and 2" are female NPT, 2.5" and 3" are wafer type.

† All sizes are female NPT.

ITEM 5: SUCTION ISOLATION VALVE

VALVE SIZE	PART NUMBER	QTY PER PUMP
1.5"	D975000-006	1
2"	D975000-007	1
2.5"	D975000-008	1
3"	D975000-009	1

4

ITEM 6: DISCHARGE ISOLATION VALVE

VALVE SIZE	PART NUMBER	QTY PER PUMP
1.5"	D975000-006	1
2"	D975000-007	1
2.5"	D975000-008	1
3"	D975000-009	1

ITEM 7: SUCTION TRANSDUCER*

PRESSURE RANGE	PART NUMBER	QTY PER BOOSTER
0-300 PSI	D500400-202	1

* Ivs systems only.

ITEM 8: SUCTION GAUGE

PRESSURE RANGE	PART NUMBER	QTY PER BOOSTER
0 to 60 PSI	975005-810	1
0 to 160 PSI	975005-811	1

ITEM 9: DISCHARGE TRANSDUCER*

PRESSURE RANGE	PART NUMBER	QTY PER BOOSTER
0 to 300 PSI	D500400-202	1
0 to 500 PSI	D500400-203	1

* Ivs systems only.

ITEM 10: DISCHARGE GAUGE

PRESSURE RANGE	PART NUMBER	QTY PER BOOSTER
0 to 60 PSI	975005-810	1
0 to 160 PSI	975005-811	1
0 to 300 PSI	975005-812	1
0 to 400 PSI	975005-813	1

ITEM 11: GAUGE ASSEMBLY ISOLATION VALVE

PRESSURE RANGE	PART NUMBER*	QTY PER BOOSTER
ALL	D975000-700	2

* Female NPT.

ITEM 12: AQUASTAT†

PRESSURE RANGE	PART NUMBER	QTY PER BOOSTER
ALL	425648-001	1

† Constant speed systems only.

TORONTO
 +1 416 755 2291

BUFFALO
 +1 716 693 8813

BIRMINGHAM
 +44 (0) 8444 145 145

MANCHESTER
 +44 (0) 8444 145 145

BANGALORE
 +91 (0) 80 4906 3555

SHANGHAI
 +86 21 3756 6696