


## ARMkool 6 Horizontal with Options

## SUBMITTAL

JOB: _____	REPRESENTATIVE: _____
_____	_____
_____	_____
ENGINEER: _____	ORDER NO: _____ DATE: _____
CONTRACTOR: _____	SUBMITTED BY: _____ DATE: _____
_____	APPROVED BY: _____ DATE: _____

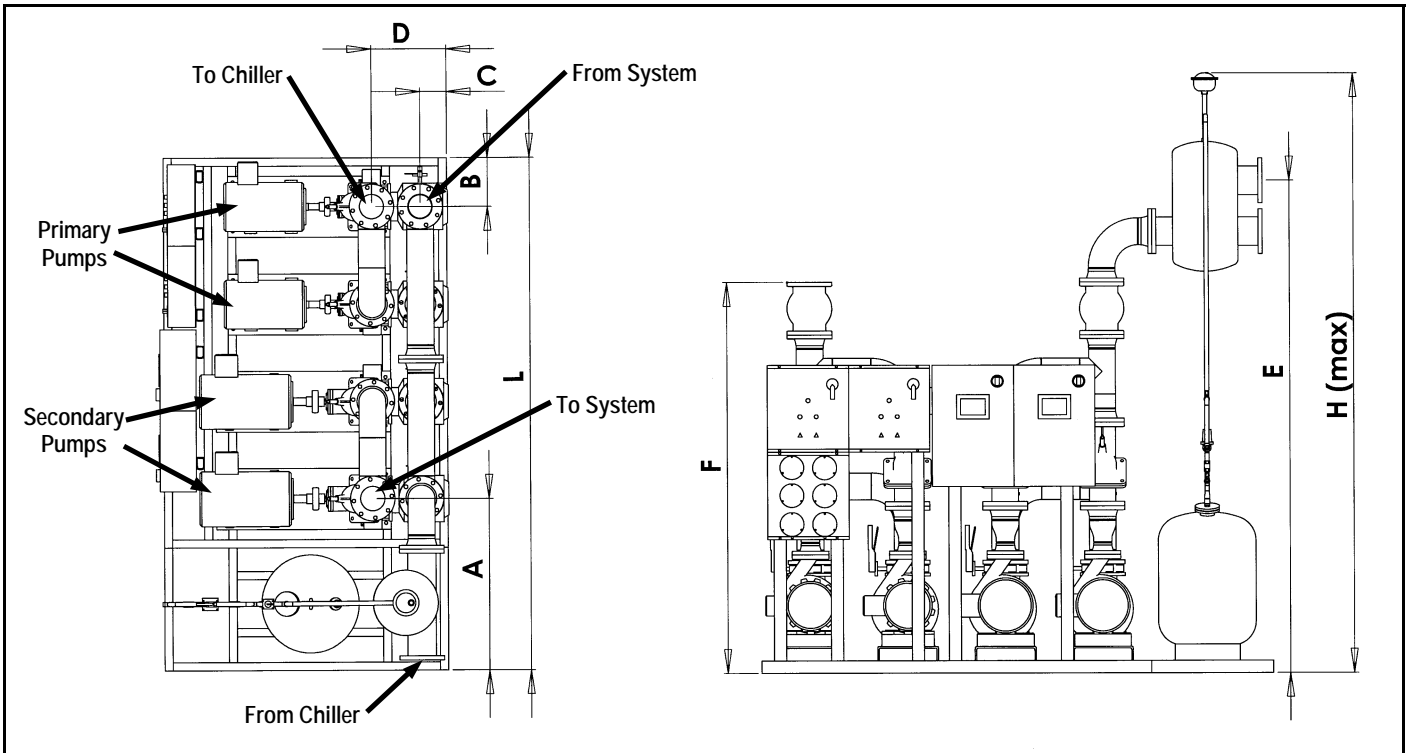

### DIMENSIONS inches (mm)

	W	L	H (max)	A	B	C	D	E	F
ARMkool 6 FS H P115 S115 AM S	72 (1829)	120 (3048)	123 (3124)	37.5 (953)	10.5 (267)	6.75 (172)	18.75 (476)	101.00 (2565)	93.50 (2375)
ARMkool 6 FS H P225 S225 AM S	72 (1829)	120 (3048)	123 (3124)	37.5 (953)	10.5 (267)	6.75 (172)	18.75 (476)	102.75 (2610)	96.75 (2458)
ARMkool 6 FS H P330 S330 AM S	72 (1829)	130 (3302)	123 (3124)	37.0 (940)	12.0 (305)	6.00 (152)	19.50 (495)	102.75 (2610)	97.25 (2470)
ARMkool 6 FS H P440 S440 AM S	76 (1930)	130 (3302)	123 (3124)	37.0 (940)	12.0 (305)	6.75 (172)	18.75 (476)	103.25 (2623)	98.25 (2496)

### WEIGHT lbs. (kg)

	Fixed Speed	Variable Speed
ARMkool 6 FS H P115 S115 AM S	6835 (3107)	7203 (3274)
ARMkool 6 FS H P225 S225 AM S	7231 (3287)	7599 (3454)
ARMkool 6 FS H P330 S330 AM S	7405 (3366)	7862 (3574)
ARMkool 6 FS H P440 S440 AM S	8577 (3899)	9179 (4172)

Armstrong Pumps Inc.  
93 East Avenue  
North Tonawanda, New York  
U.S.A. 14120-6594  
Tel: (716) 693-8813  
Fax: (716) 693-8970

S.A. Armstrong Limited  
23 Bertrand Avenue  
Toronto, Ontario  
Canada, M1L 2P3  
Tel: (416) 755-2291  
Fax: (416) 759-9101



Armstrong Pumps Limited  
Peartree Road, Stanway  
Colchester, Essex  
United Kingdom, CO3 0LP  
Tel: 01206-579491  
Fax: 01206-760532

Armstrong Darling  
2200 Place Transcanadienne  
Montreal, Quebec  
Canada, H9P 2X5  
Tel: (514) 421-2424  
Fax: (514) 421-2436

