



DESIGN ENVELOPE VERTICAL IN-LINE FIREPAK STANDARD | SUBMITTAL

File No: F100.4300
Date: FEBRUARY 04, 2026
Supersedes: NEW
Date: NEW



Job: _____ Representative: _____
Order no.: _____ Date: _____
Engineer: _____ Submitted by: _____ Date: _____
Contractor: _____ Approved by: _____ Date: _____

TAG/REF:									
PUMP DATA	FLOW	HEAD	MOTOR DATA	HP	RPM	VOLT	PH	HZ	ENCLOSURE

☐ SUCTION ON RIGHT

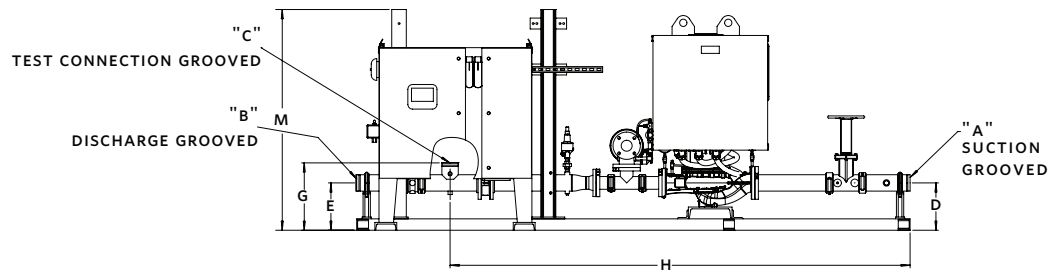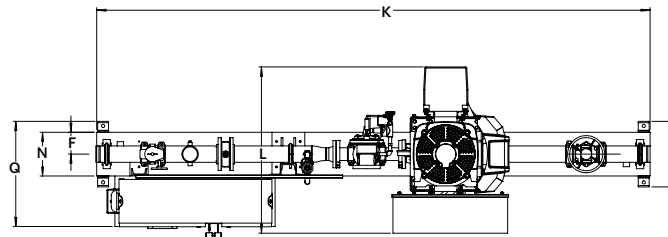

☐ SUCTION ON LEFT

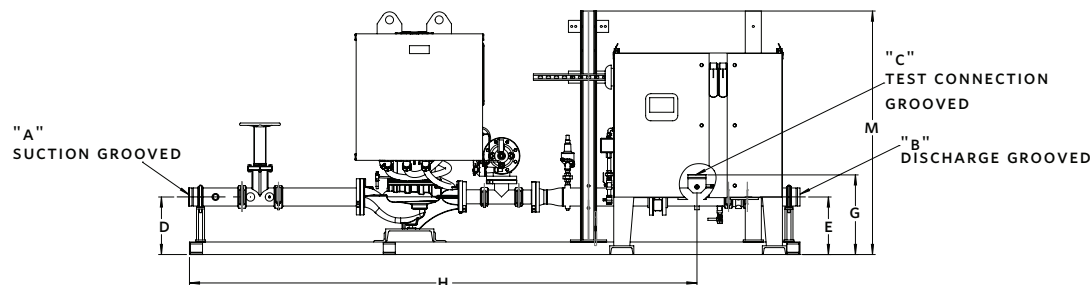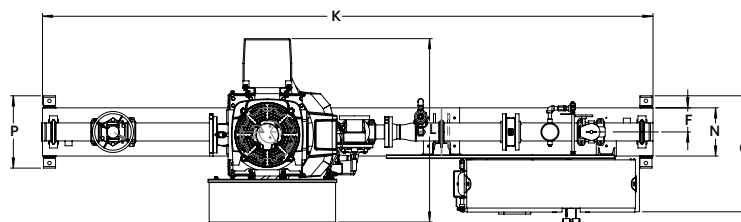

Design Envelope Vertical In-Line Firepak
Standard

SUBMITTAL

2

PUMP DATA

FLOW (GPM)	PUMP MODEL	DIMENSIONS (INCHES)															MAX SHIPPING WEIGHT* (LBS)
		CONNECTION (GROOVED)								OVERALL DIMENSION (MAX)			BASE DIMENSION				
		A	B	C	D	E	F	G	H	K (length)	L (width)	M (height)	N	P	Q (MAX)		
300	DE4×3×9PF	4.00	4.00	4.00	13.00	13.00	6.00	18.50	126.94	152.00	45.67	60.63	12.00	18.00	34.88	3173	
400	DE4×3×9PF	4.00	4.00	4.00	13.00	13.00	6.00	18.50	126.94	152.00	45.67	60.63	12.00	18.00	34.88	3173	
450	DE4×3×9PF	6.00	6.00	6.00	11.94	13.00	6.00	19.50	123.55	152.00	45.67	60.63	12.00	18.00	34.88	3343	
500	DE4×3×9PF	6.00	6.00	6.00	11.94	13.00	6.00	19.50	123.55	152.00	45.67	60.63	12.00	18.00	34.88	3343	
300	DE4×3×10PF	4.00	4.00	4.00	14.33	14.33	6.00	19.83	126.36	152.00	50.66	60.63	12.00	18.00	34.88	3293	
400	DE4×3×10PF	4.00	4.00	4.00	14.33	14.33	6.00	19.83	126.36	152.00	50.66	60.63	12.00	18.00	34.88	3293	
450	DE4×3×10PF	6.00	6.00	6.00	13.31	14.37	6.00	20.94	123.48	152.00	50.66	68.48	12.00	18.00	34.88	3463	
500	DE4×3×10PF	6.00	6.00	6.00	13.31	14.37	6.00	20.94	123.48	152.00	50.66	68.48	12.00	18.00	34.88	3463	
400	DE5×4×9PF	4.00	4.00	4.00	16.41	15.88	6.00	21.44	126.36	152.00	53.09	75.50	12.00	18.00	34.88	3283	
450	DE5×4×9PF	6.00	6.00	6.00	15.34	15.88	6.00	22.44	123.82	152.00	53.09	74.63	12.00	18.00	34.88	3453	
500	DE5×4×9PF	6.00	6.00	6.00	15.34	15.88	6.00	22.44	123.82	152.00	53.09	74.63	12.00	18.00	34.88	3453	
750	DE5×4×9PF	6.00	6.00	6.00	15.34	15.88	6.00	22.44	123.82	152.00	53.09	74.63	12.00	18.00	34.88	3453	
400	DE5×4×10PF	4.00	4.00	4.00	16.00	15.51	6.00	21.07	126.36	152.00	53.90	75.25	12.00	18.00	34.88	3349	
450	DE5×4×10PF	6.00	6.00	6.00	14.97	15.54	6.00	22.01	123.63	152.00	53.90	75.25	12.00	18.00	34.88	3519	
500	DE5×4×10PF	6.00	6.00	6.00	14.97	15.54	6.00	22.01	123.63	152.00	53.90	75.25	12.00	18.00	34.88	3519	
750	DE5×4×10PF	6.00	6.00	6.00	14.97	15.54	6.00	22.01	123.63	152.00	53.90	75.25	12.00	18.00	34.88	3519	

TORONTO

+1 416 755 2291

NOTE:

* Max Shipping Weight does not include Fire Pump, Jockey Pump, or Controller weights

BUFFALO

+1 716 693 8813

DROITWICH SPA

+44 8444 145 145

MANCHESTER

+44 8444 145 145

BANGALORE

+91 80 6510 3555

SHANGHAI

+86 21 5237 0909

BEIJING

+86 21 5237 0909

SÃO PAULO

+55 11 4785 1330

LYON

+33 4 20 10 26 21

DUBAI

+971 4 887 6775

JIMBOLIA

+40 256 360 030

FRANKFURT

+49 6173 999 77 55

ARMSTRONG FLUID TECHNOLOGY®
ESTABLISHED 1934

ARMSTRONGFLUIDTECHNOLOGY.COM