




**EXTENDED SPEED**

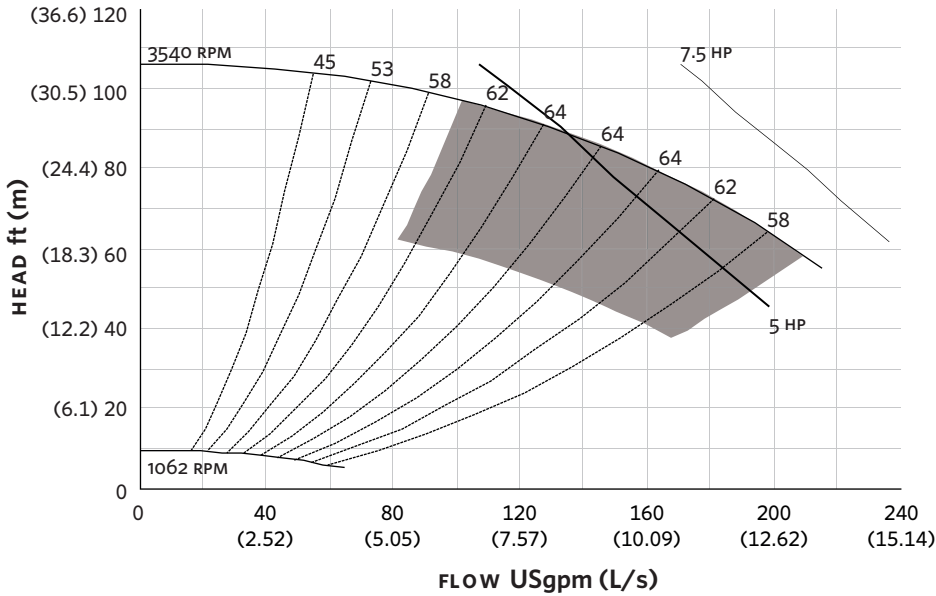

Performance curves are for reference only.  
Confirm current performance data with Armstrong ACE Online selection software.

**DIMENSION DATA**

**INDOOR**  
(UL TYPE 12/ODP)

- Frame size:** 184JM
- Size:** 3×1.5×6
- HP:** 5
- RPM:** 3600
- A:** 9.08 (231)
- B:** 7.09 (180)
- C MAX:** 20.21 (513)
- D1:** 5.25 (133)
- D2:** 4.50 (114)
- 2E:** 7.50 (191)
- F:** 5.50 (140)
- H:** 0.47 (12)
- HD:** 6.65 (169)
- HI:** 21.64 (550)
- HV:** 13.67 (347)
- N:** 6.28 (160)
- NAN1:** 6.00 (152)
- X:** 6.50 (165)
- Y:** 4.00 (102)
- Casing foot hole:** 0.63 (16)
- Weight:** 269 (122.0)

Dimensions - inch (mm)  
Weight - lbs (kg)

**INDOOR**

- TORONTO**  
+1 416 755 2291
- BUFFALO**  
+1 716 693 8813
- BIRMINGHAM**  
+44 (0) 8444 145 145
- MANCHESTER**  
+44 (0) 8444 145 145
- BANGALORE**  
+91 (0) 80 4906 3555
- SHANGHAI**  
+86 21 3756 6696
- SÃO PAULO**  
+55 11 4781 5500

