

HORIZONTAL SPLIT CASE PUMP | SERIES 4600F |
DIESEL DRIVEN | 12x8x18F/NF | SUBMITTAL

File No: F46.566
Date: DECEMBER 27, 2022
Supersedes: F46.566
Date: SEPTEMBER 25, 2018

Job: _____ Representative: _____

Order no.: _____ Date: _____

Engineer: _____ Submitted by: _____ Date: _____

Contractor: _____ Approved by: _____ Date: _____

PUMP DESIGN DATA

Flow: _____

Head: _____

ENGINE DESIGN DATA

HP: _____ RPM: _____

Bat. Voltage: _____ Tank size: _____

Other: _____

NOTES

- 1 Std. Discharge flange thickness ANSI 250#.
- 2 Coupling guard not shown.
- 3 All dimensions for engine connections are with reference to engine manufacturer's installation drawings.
- 4 Do not use for construction unless certified.
- 5 Right hand rotation only.

FLANGE RATING

- ANSI 125# STD¹
- ANSI 125# Suction
250# Discharge
- ANSI 250#
- PN 16



FIRE PUMP LISTING

- UL
- ULC
- FM

ACCESSORIES

- Exhaust system
- Fuel system
- Cooling system (mounted on engine)
- Battery system

12x8x18F/NF	HORIZONTAL SPLIT CASE DIESEL DRIVEN	DIMENSIONS inches (mm)							WEIGHT
		C	HA	HB	HE	HF	HM	Z	lbs (kg)
Clarke	JU6H series	105.48 (2679)	32.00 (813)	106.00 (2692)	30.00 (762)	51.00 (1295)	43.25 (1099)	16.50 (419)	4577 (2076.1)
	JW6H series	111.78 (2839)	32.00 (813)	110.00 (2794)	30.00 (762)	35.25 (895)	46.95 (1193)	16.50 (419)	4968 (2253.2)
Cummins	CFP5E series	95.37 (2422)	32.00 (813)	98.00 (2489)	30.00 (762)	47.00 (1194)	52.78 (1341)	16.50 (419)	4113 (1865.6)
	CFP7E series	106.32 (2701)	32.00 (813)	106.00 (2692)	30.00 (762)	51.00 (1295)	52.78 (1341)	16.50 (419)	4323 (1960.8)
	CFP9E series	108.11 (2746)	32.00 (813)	106.00 (2692)	30.00 (762)	51.00 (1295)	54.88 (1394)	16.50 (419)	4748 (2153.7)
	CFP15E series	132.12 (3356)	40.00 (1016)	130.00 (3302)	38.00 (965)	63.00 (1600)	46.72 (1187)	16.50 (419)	7525 (3413.4)

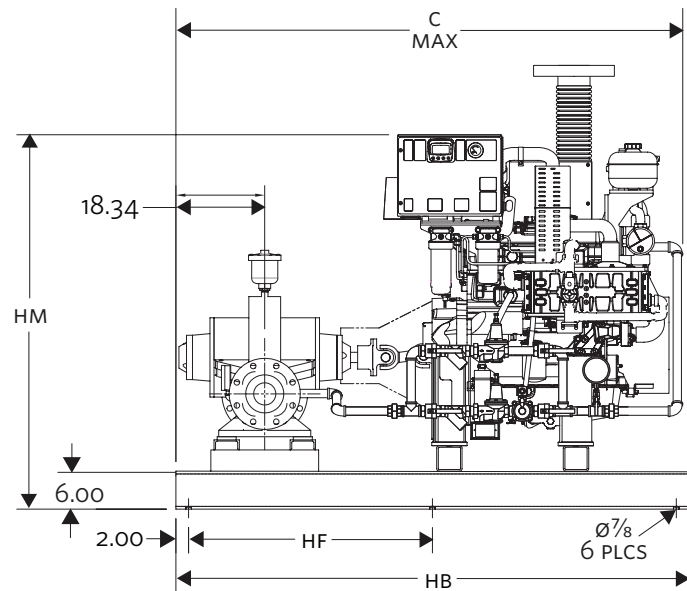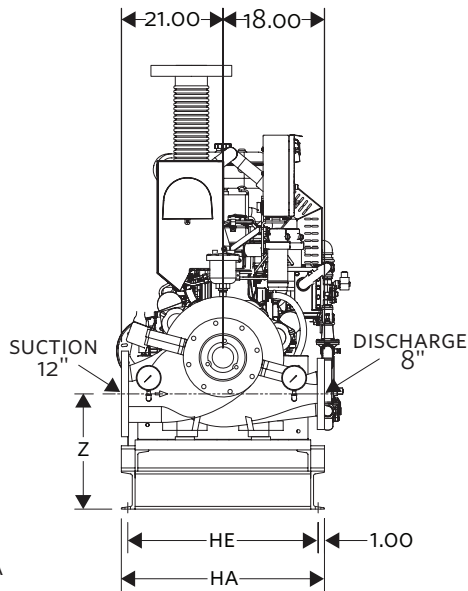

- TORONTO
+1 416 755 2291
- BUFFALO
+1 716 693 8813
- DROITWICH SPA
+44 121 550 5333
- MANCHESTER
+44 161 223 2223
- BANGALORE
+91 80 4906 3555
- SHANGHAI
+86 21 5237 0909
- BEIJING
+86 21 5237 0909
- SÃO PAULO
+55 11 4785 1330
- LYON
+33 4 26 83 78 74
- DUBAI
+971 4 887 6775
- JIMBOLIA
+40 256 360 030